




<b>Order Code</b>	<b>TCK-075</b>
<b>Inductance</b> (each winding)	33.3 $\mu\text{H} \pm 20\%$ (at 10 kHz / 50 mV)
<b>Impedance</b> (DCR)	9 m $\Omega$ max.
<b>Rated Current</b>	4 A max.
<b>Rated Voltage</b>	500 VDC max. (between windings)
<b>Operating Temperature</b>	-40°C to +105°C
<b>RoHS Exemptions</b>	No Exemptions
<b>Overview Link</b>	<a href="http://www.tracopower.com/overview/tck-075">www.tracopower.com/overview/tck-075</a>

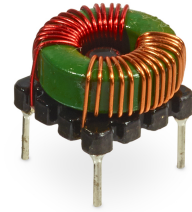

### Impedance Curve

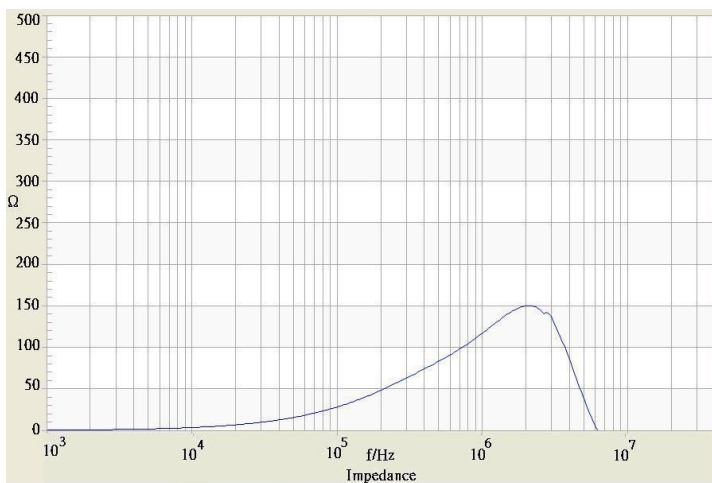

### Outline Dimensions

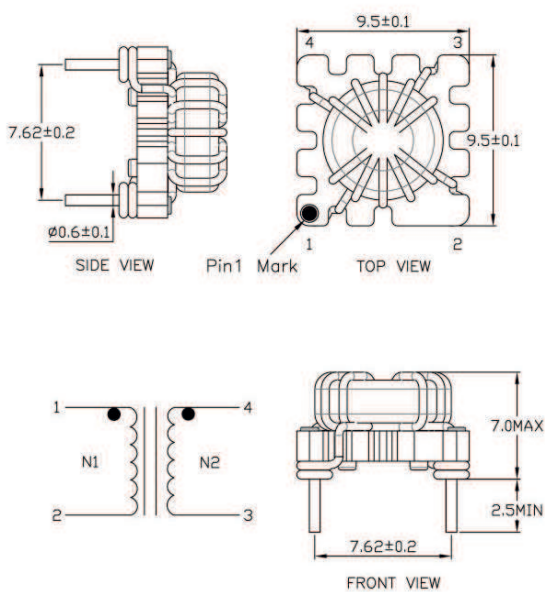

All specifications valid at +25°C, unless otherwise stated.