



Order Code	TCK-108
Inductance	3.3 μ H \pm 20% (at 100 kHz / 250 mV)
Impedance (DCR)	50 m Ω max.
Rated Current	3.3 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-108

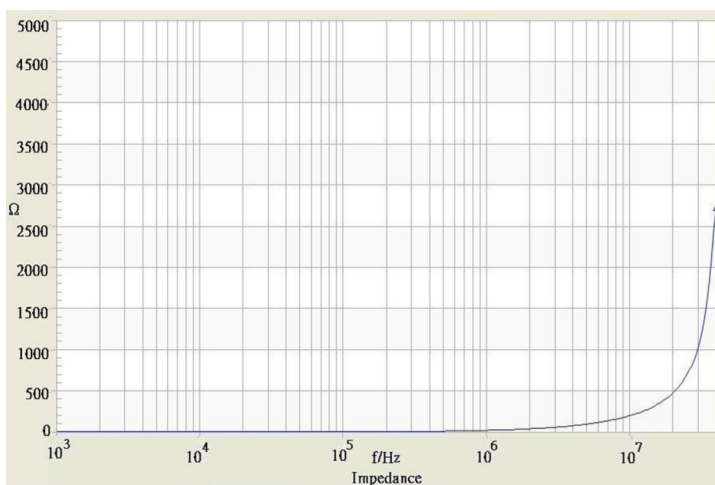

Impedance Curve



Outline Dimensions

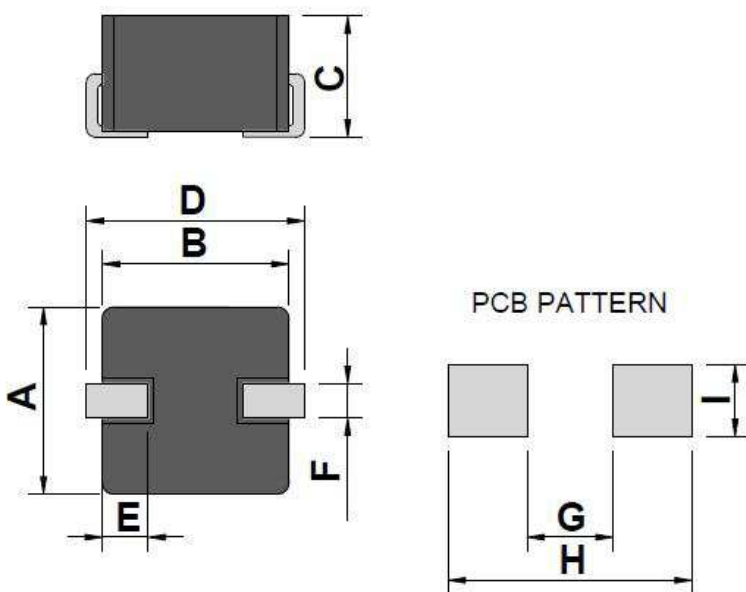

Dimensions [mm]

Dimension	Value [mm]
A	4.0 \pm 0.3
B	4.0 \pm 0.3
C	2.1 max.
D	4.7 max.
E	1.0 \pm 0.3
F	0.6 \pm 0.1
G	2.2
H	6.0
I	1.5

All specifications valid at +25°C, unless otherwise stated.