






Order Code	TCK-111
Inductance	10 μ H \pm 20% (at 1 kHz / 1 V)
Impedance (DCR)	182 m Ω max.
Rated Current	1.15 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-111



Impedance Curve

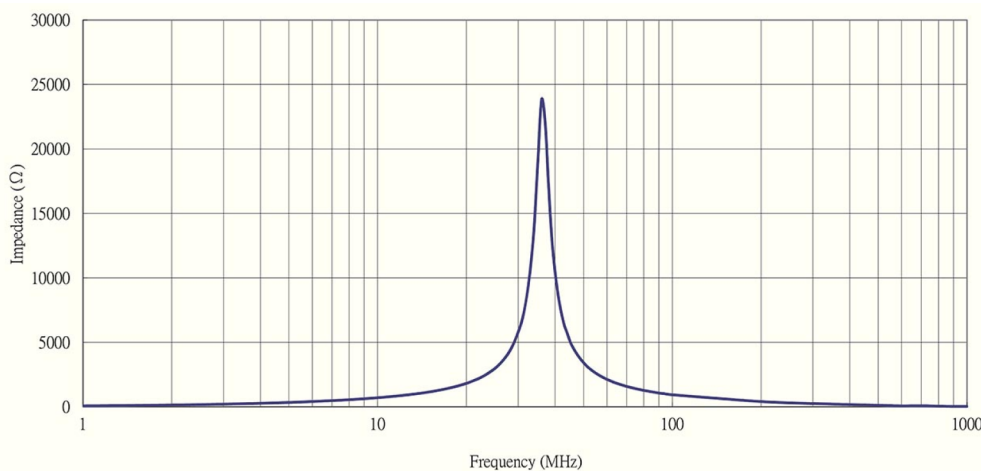

Outline Dimensions

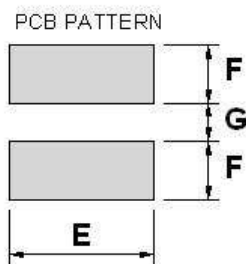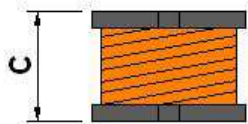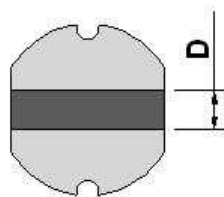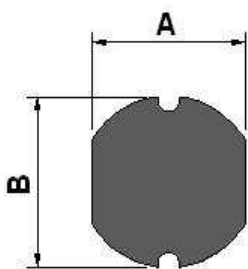

Dimensions [mm]

A	4.0 \pm 0.5
B	4.5 \pm 0.5
C	3.2 \pm 0.5
D	1.2 typ.
E	4.5
F	1.75
G	1.5

All specifications valid at +25°C, unless otherwise stated.