



Order Code	TCK-116
Inductance	10 μ H \pm 20% (at 100 kHz / 250 mV)
Impedance (DCR)	200 m Ω max.
Rated Current	2.3 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-116



Impedance Curve

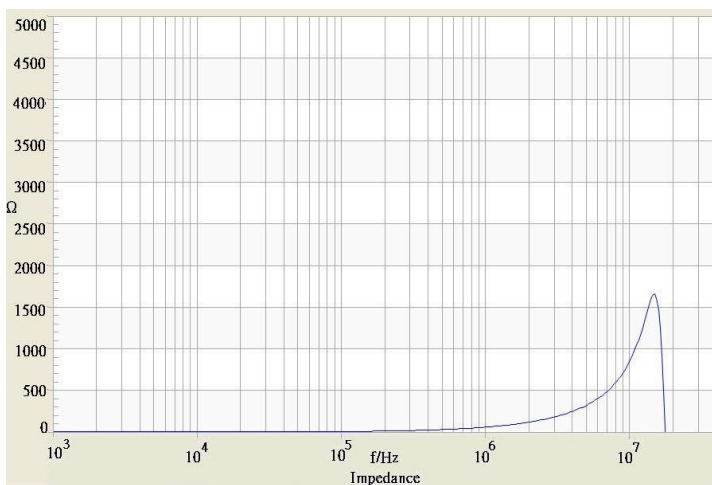

Outline Dimensions

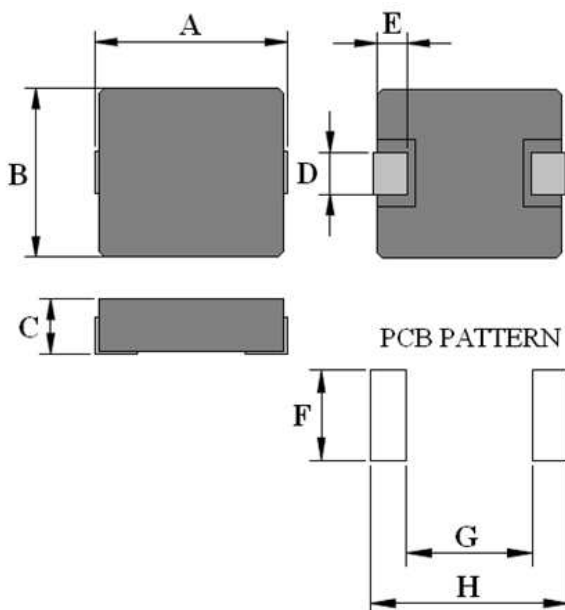

Dimensions [mm]	
A	5.4 max.
B	4.7 \pm 0.3
C	2.2 max.
D	2.0 \pm 0.3
E	1.0 \pm 0.3
F	2.5
G	3.0
H	7.0

All specifications valid at +25°C, unless otherwise stated.