



Order Code	TCK-149
Inductance	22 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	240 m Ω max.
Rated Current	1.1 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-149




Impedance Curve

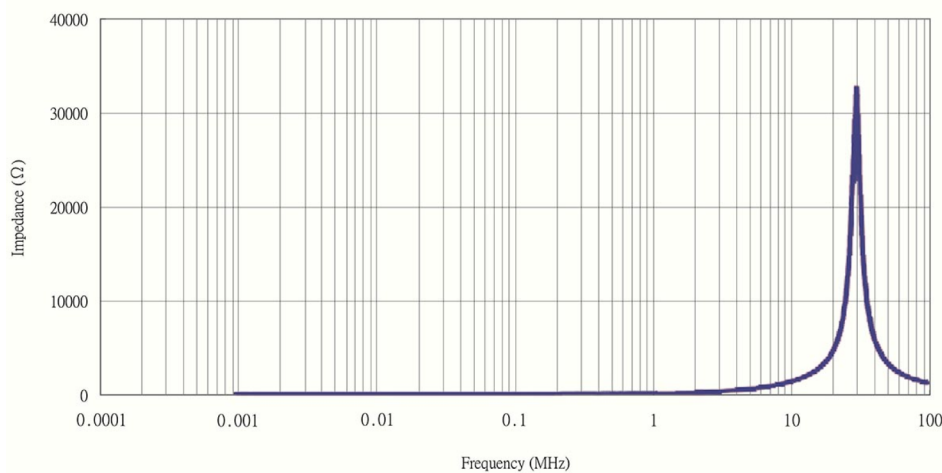

Outline Dimensions

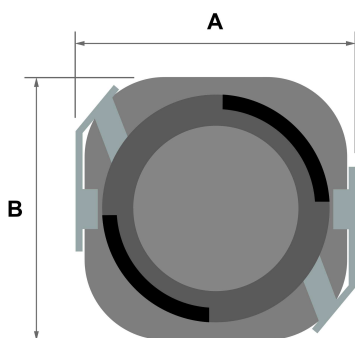

Dimensions [mm]	
A	5.3 \pm 0.4
B	5.0 \pm 0.4
C	2.7 \pm 0.5
D	2
E	2
F	2

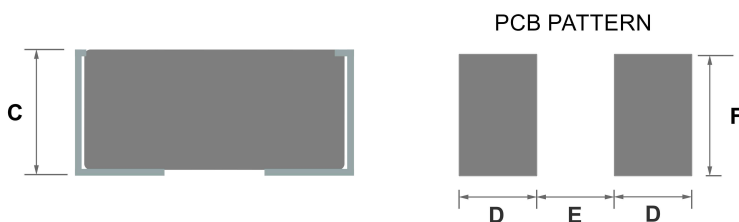

All specifications valid at +25°C, unless otherwise stated.