





Order Code	TCK-178
Inductance	6.8 μ H \pm 20% (100 kHz / 1 V)
Impedance (DCR)	50 m Ω max.
Rated Current	2.84 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-178

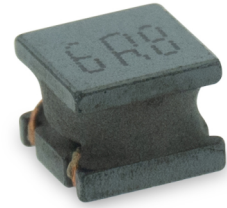

Impedance Curve

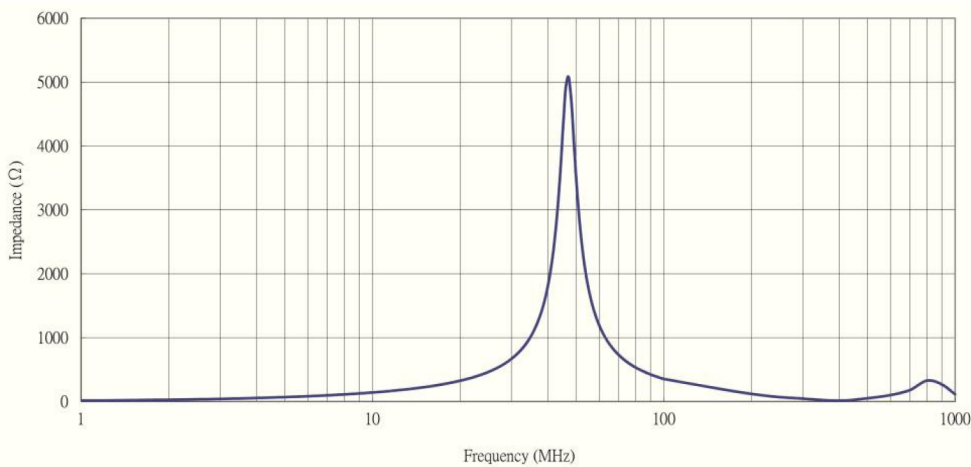

Outline Dimensions

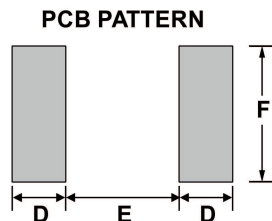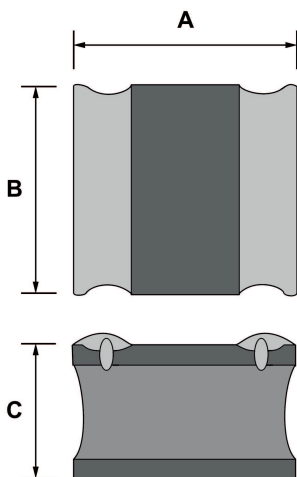

Dimensions [mm]	
A	4.9 \pm 0.4
B	4.9 \pm 0.4
C	4.2 max.
D	1.5
E	2.1
F	4.0

All specifications valid at +25°C, unless otherwise stated.