




Order Code	TCK-182
Inductance	100 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	589 m Ω max.
Rated Current	0.8 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-182

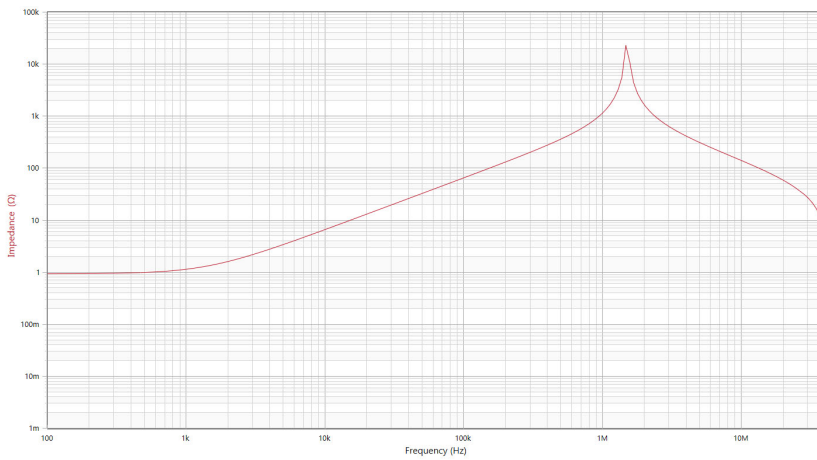


Impedance Curve



Outline Dimensions

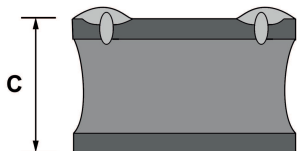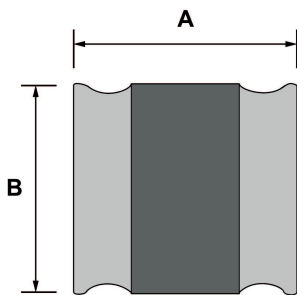

PCB PATTERN

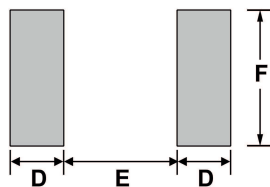

Dimensions [mm]

A	4.9 \pm 0.4
B	4.9 \pm 0.4
C	4.2 max.
D	1.5
E	2.1
F	4.0

All specifications valid at +25°C, unless otherwise stated.