




Order Code	TCK-183
Inductance (each winding)	545 μ H \pm 35% (at 100 kHz / 100 mV)
Impedance (DCR)	9 m Ω max.
Rated Current	13 A max.
Operating Temperature	40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-183

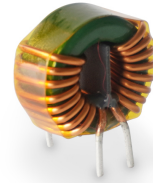


Impedance Curve

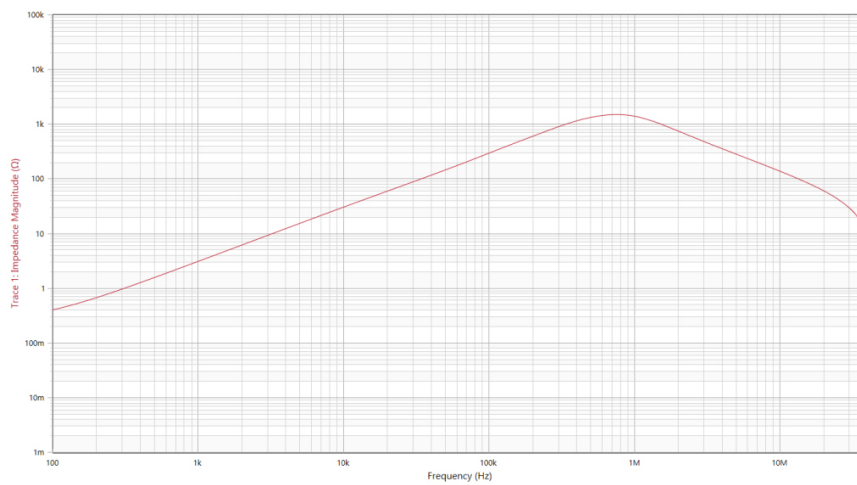

Outline Dimensions

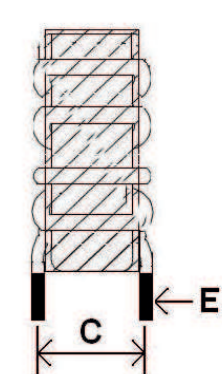

SIDE VIEW

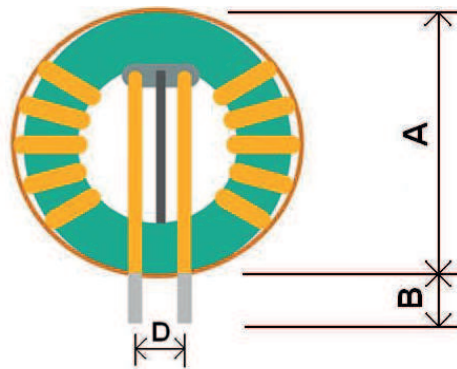

FRONT VIEW

Dimensions [mm]

A	14.45 max.
B	5.0 \pm 2
C	10.0 \pm 1
D	4.0 \pm 1
E	\varnothing 1.0 \pm 1

All specifications valid at +25°C, unless otherwise stated.