



Order Code	TCK-183
Inductance (each winding)	545 $\mu\text{H} \pm 35\%$ (at 100 kHz / 100 mV)
Impedance (DCR)	9 m Ω max.
Rated Current	13 A max.
Operating Temperature	40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-183

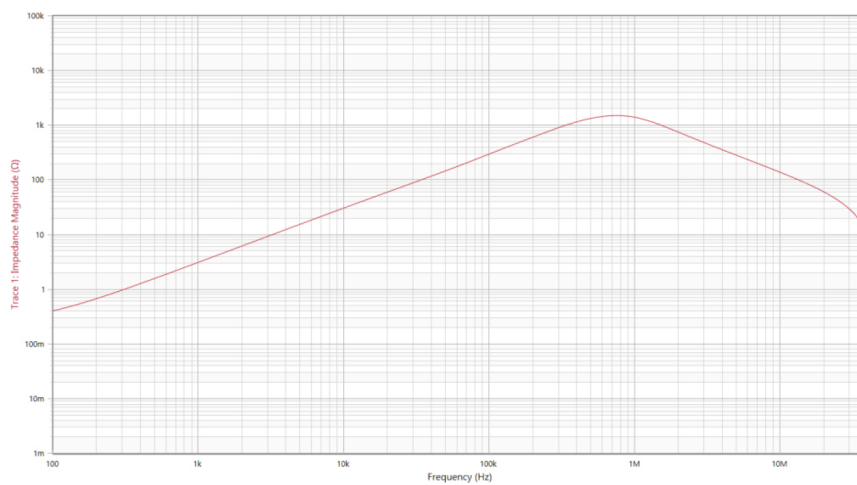

Impedance Curve



Outline Dimensions

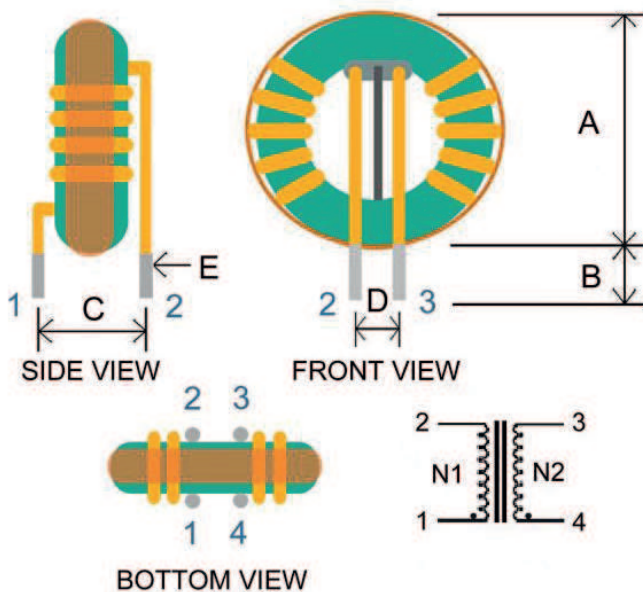

Dimensions [mm]	
A	14.45 max.
B	5.0 ± 2
C	10.0 ± 1
D	4.0 ± 1
E	$\varnothing 1.0 \pm 1$

All specifications valid at +25°C, unless otherwise stated.