



Order Code	TCK-184
Inductance	4.7 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	15 m Ω max.
Rated Current	12 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-184

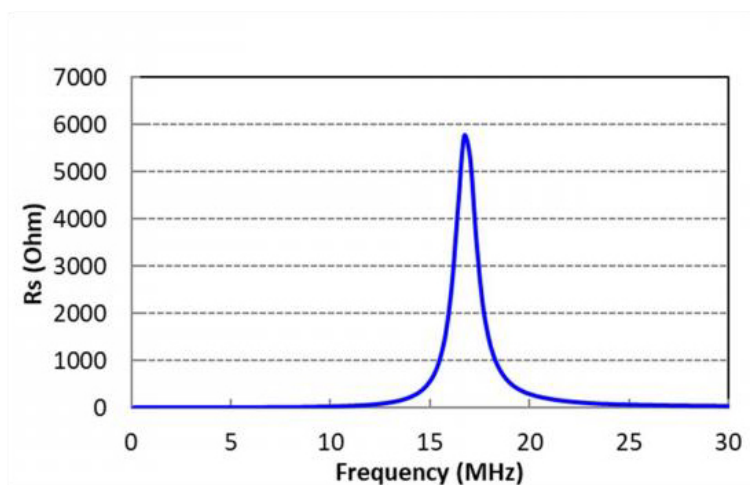


Impedance Curve



Outline Dimensions

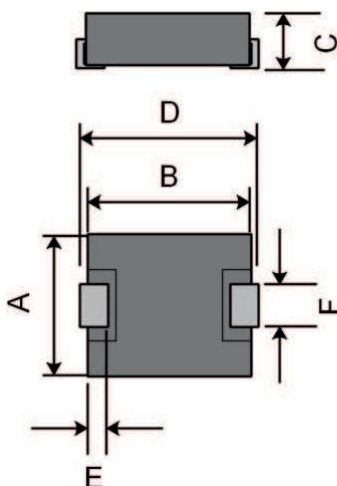

PCB PATTERN

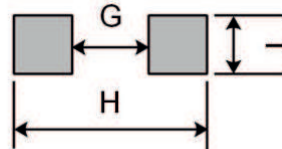

Dimensions [mm]

A	12.6 \pm 0.4
B	12.6 \pm 0.4
C	4.8 \pm 0.4
D	13.45 \pm 0.55
E	2.0 \pm 0.7
F	3.0 \pm 0.7
G	8.0
H	14.5
I	5.0

All specifications valid at +25°C, unless otherwise stated.