



Order Code	TCK-195
Inductance	2.2 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	7 m Ω max.
Rated Current	12 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-195

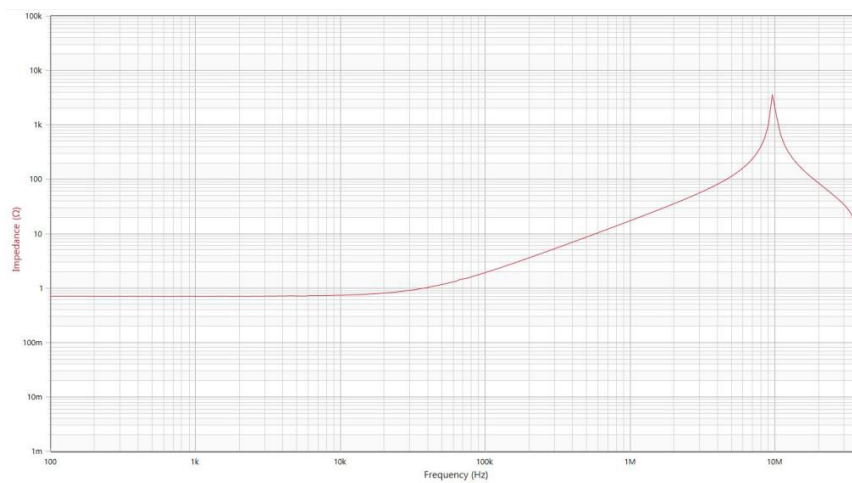


Impedance Curve



Outline Dimensions

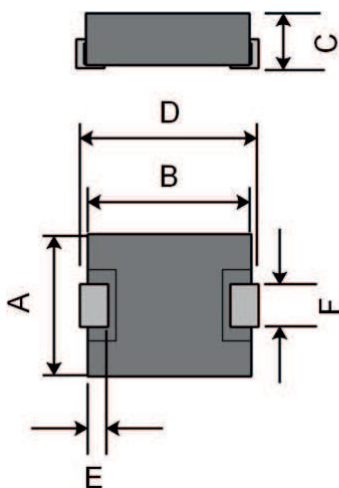

PCB PATTERN

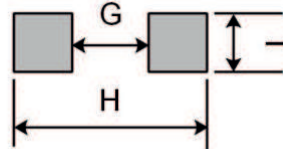

Dimensions [mm]

A	10.0 \pm 0.5
B	10.0 \pm 0.5
C	4.2 max.
D	11.7 max.
E	2.0 \pm 0.7
F	3.0 \pm 0.7
G	5.4
H	13.6
I	4.1

All specifications valid at +25°C, unless otherwise stated.