



Order Code	TCK-196
Inductance	15 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	115 m Ω max.
Rated Current	3 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-196



Impedance Curve

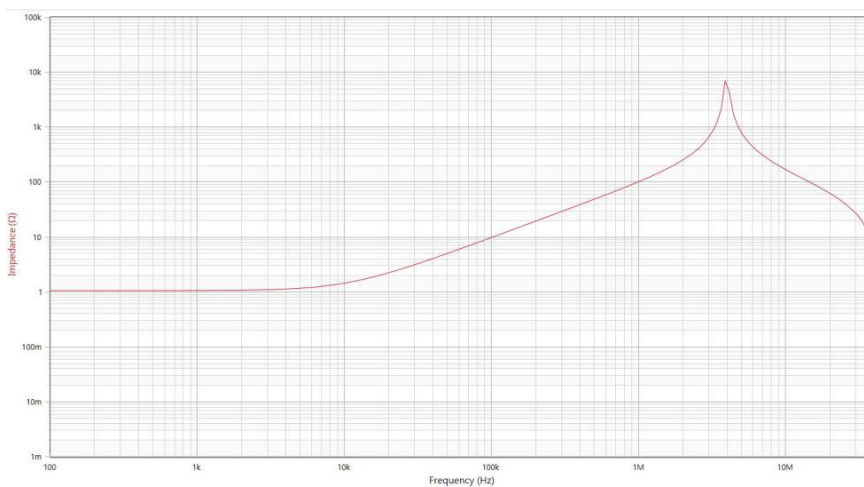

Outline Dimensions

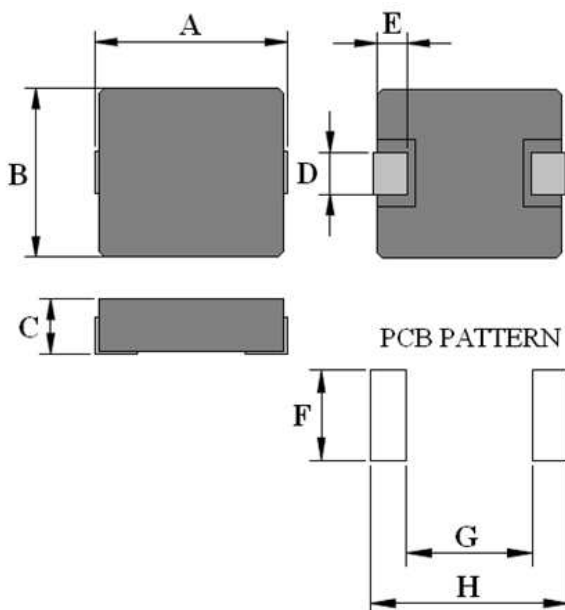

Dimensions [mm]	
A	7.5 max.
B	7.0 max.
C	3.2 max.
D	3.0 \pm 0.5
E	1.6 \pm 0.5
F	3.5
G	3.7
H	8.4

All specifications valid at +25°C, unless otherwise stated.