





Order Code	TCK-197
Inductance	82 μ H \pm 20% (at 1 MHz / 1 V)
Impedance (DCR)	365 m Ω max.
Rated Current	0.98 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-197

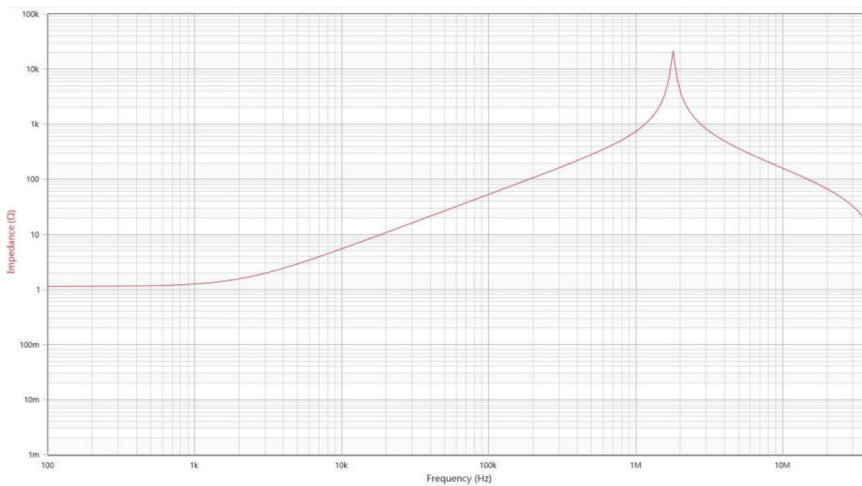

Impedance Curve



Outline Dimensions

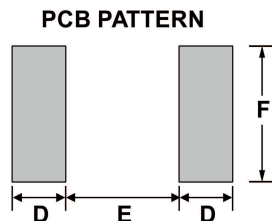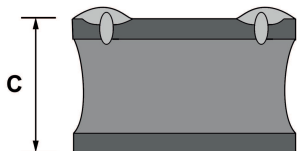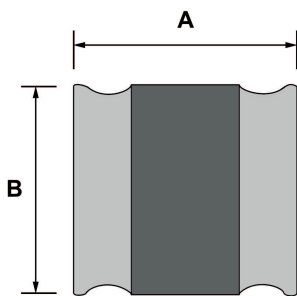

Dimensions [mm]

Dimension	Value
A	6.5 max.
B	6.5 max.
C	4.7 max.
D	2.35
E	1.8
F	5.1

All specifications valid at +25°C, unless otherwise stated.