





Order Code	TCK-198
Inductance	33 μ H \pm 20% (100 kHz / 1 V)
Impedance (DCR)	216 m Ω max.
Rated Current	1.2 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-198

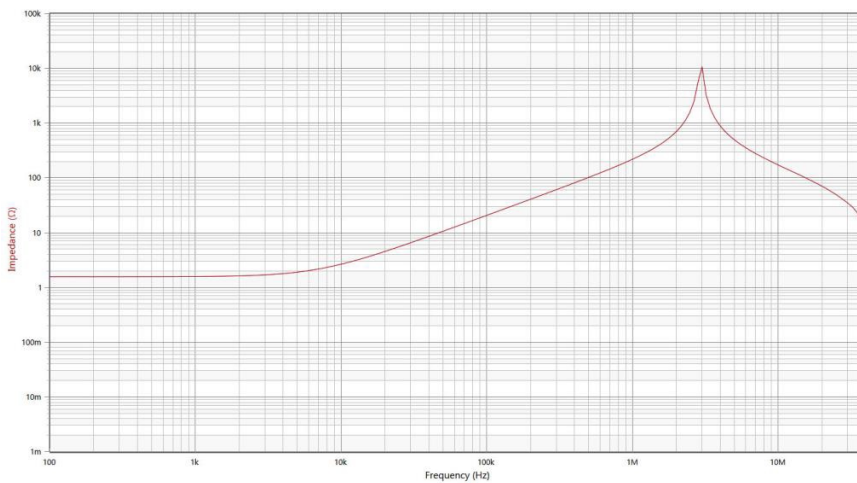

Impedance Curve



Outline Dimensions

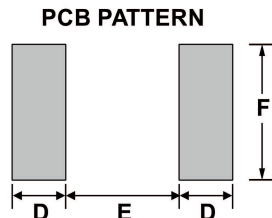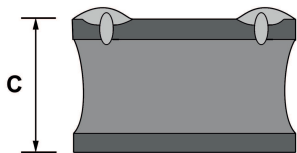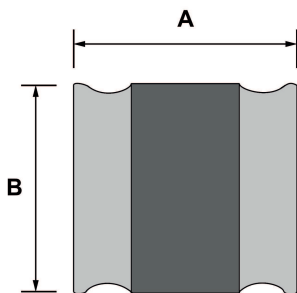

Dimensions [mm]

A	5.35 max.
B	5.35 max.
C	4.2 max.
D	1.5
E	2.2
F	4

All specifications valid at +25°C, unless otherwise stated.